




# iStation Modules, SVGA with 3.5 MM Stereo Jack and XLR, Screw Terminal, 2-Unit

By Bryant  
Catalog # [IM153X2OW](#)

iStation Modules, SVGA with 3.5 MM Stereo Jack and XLR, Screw Terminal, 2-Unit

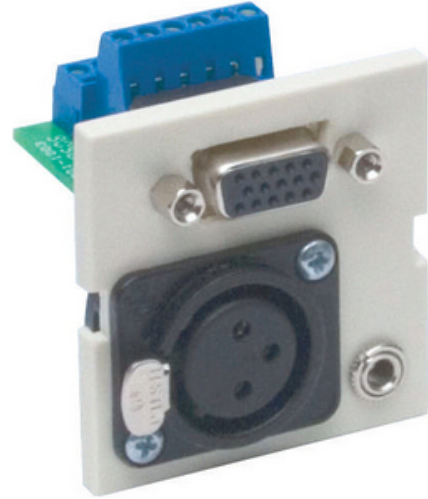

## Application

Loaded Pro AV Modules

## General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION Pro Audio D-Style Connections
Material - Mounting Hardware	Snap-On- Snap-Fit
Temperature Rating	Per TIA
Type	15-Pin Screw Term
UPC	662620290089

## Dimensions

Display Size Standard Sized Product

## Electrical Ratings

Connectivity	Plug-N-Play
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

## Logistics

Carton Quantity 25

## Product Assets



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-IM153X2OW-SPEC-EN | REV 7/2023