


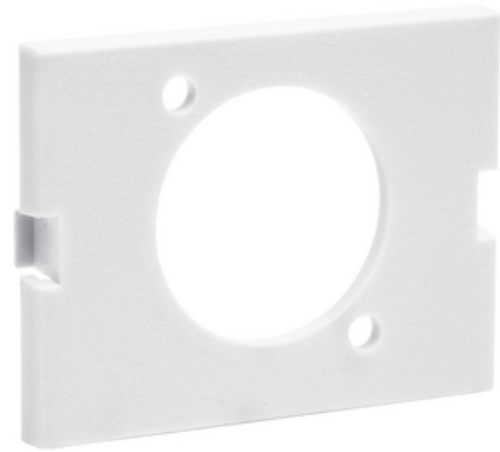

iStation Module, Audio/Video, Unloaded, 1.5-Unit, White, 10 Pack

By Bryant
Catalog # [IMAVB15W](#)

iStation Module, Audio/Video, Unloaded, 1.5-Unit, White, 10 Pack



Application

AV Panel Mount Module Unloaded

General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION Pro Audio D-Style Connections
Material - Mounting Hardware	Snap-On- Snap-Fit
Style	XLR
Temperature Rating	Per TIA
Type	Unloaded
UPC	662620284811

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Connectivity	Plug-N-Play
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

Product Assets

Related Products

- [14S10 - 1/4" Audio Jack, Solder Type, Pane IMount, 10 Pack](#)
- [XLR10 - XLR Connector, Solder Type, Panel Mount, 3-Pin, 10 Pack](#)
- [XLRST10 - XLR Connector, Screw Terminal, Panel Mount, 3-Pin, 10 Pack](#)
- [IMAVB15EI - iStation Module, Audio/Video, Unloaded, 1.5-Unit, Electric Ivory, 10 Pack](#)
- [IMAVB15OW - iStation Module, Audio/Video, Unloaded, 1.5-Unit, Office White, 10 Pack](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-IMAVB15W-SPEC-EN | REV 7/2023