


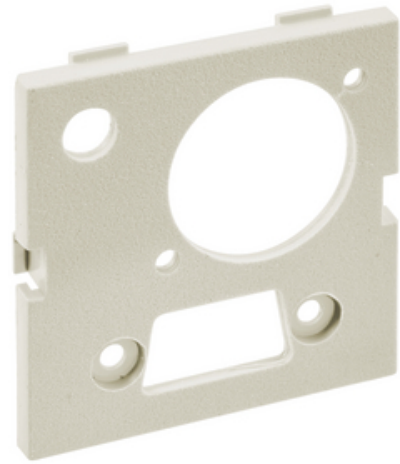

iStation Modules, 15-Pin, XLR, 3.5 MM Stereo Jack, Unloaded, 2-Unit, Electric Ivory

By Bryant
Catalog # [IMB153X2EI](#)

iStation Modules, 15-Pin, XLR, 3.5 MM Stereo Jack, Unloaded, 2-Unit, Electric Ivory



Application

15/9 Pin/HDMI, Pro AV, 3.5mm

General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION Front-Loading Modules
Material - Mounting Hardware	Snap-On- Snap-Fit
Style	3.5mm Stereo Jack
Temperature Rating	Per TIA
Type	VGA
UPC	662620291994

Dimensions

Display Size Standard Sized Product

Electrical Ratings

Connectivity	Plug-N-Play
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

Logistics

Carton Quantity 20

Product Assets

[Catalog Page - Bryant R-17 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-IMB153X2EI-SPEC-EN | REV 7/2023