




# Plates, Wall Phone, 6-Position 4-Conductor, Screw Terminal, Electric Ivory

By Bryant  
Catalog # [NS722I](#)

Plates, Wall Phone, 6-Position 4- Conductor, Screw Terminal, Electric Ivory

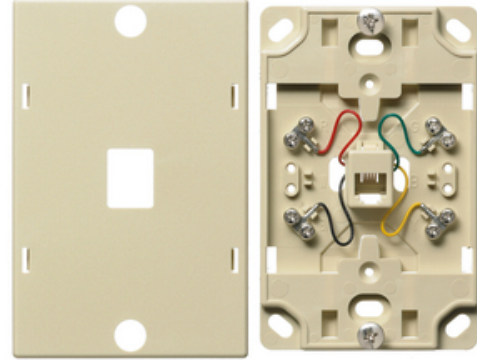

## Application

Communications

## General

Color	Ivory
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	1) 6-Position 4-Conductor Jack
Material	Nylon
Material - Mounting Hardware	Screw Mounting
Size	Standard
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	Telephone Jack
UPC	883778502644

## Dimensions

Display Size Standard Sized Product

## Electrical Ratings

Connectivity	Screw Terminals
Contact Resistance	Per TIA
Insertion Loss	Per TIA

## Certifications and Compliance

Industry Standard(s) UL Listed

## Logistics

Carton Quantity 10

## Product Assets

[Catalog Page - Bryant R-14 Catalog page](#)  
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-NS722I-SPEC-EN | REV 7/2023