


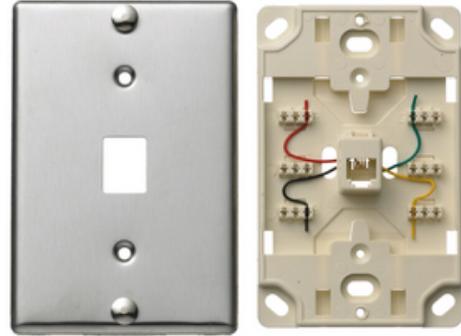

Wall Phone Plate, 6-Position 4-Conductor, 110 Terminals, Stainless Steel

By Bryant
Catalog # [NS723SS](#)

Wall Phone Plate, 6-Position 4- Conductor, 110 Terminals, Stainless Steel



Features

- Meets FCC part 68
- Available in high impact-resistant thermoplastic or stainless steel

Application

Communications

General

Color	Stainless
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	1) 6-Position 4-Conductor Jack
Material	Stainless Steel
Material - Mounting Hardware	Screw Mounting
Size	Standard
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	Telephone Jack
UPC	883778502637

Dimensions

Display Size Standard Sized Product

Electrical Ratings

Connectivity	110 Punch Down
Contact Resistance	Per TIA
Insertion Loss	Per TIA

Certifications and Compliance

Industry Standard(s) UL Listed

Logistics

Carton Quantity 10

Product Assets

[Catalog Page - Bryant R-14 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-NS723SS-SPEC-EN | REV 7/2023