


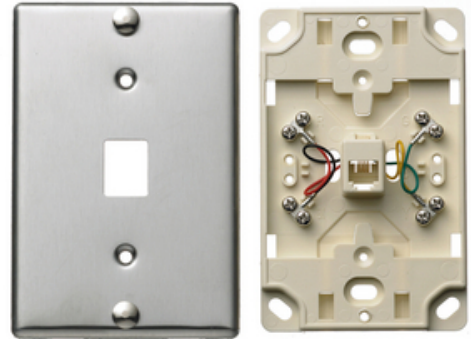

Plates, Wall Phone, 6-Position 4-Conductor, Screw Terminal, Stainless Steel

By Bryant
Catalog # [NS726SS](#)

Plates, Wall Phone, 6-Position 4- Conductor, Screw Terminal, Stainless Steel



General

Application	Communications
Catalog Number	NS726SS
Color	Stainless
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	1) 6-Position 4-Conductor Jack
Material	Stainless Steel
Material - Mounting Hardware	Screw Mounting
Size	Standard
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	Telephone Jack
	Telephone Jack
UPC	883778502675

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Connectivity	Screw Terminals
Contact Resistance	Per TIA
Insertion Loss	Per TIA

Certifications And Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog Page - PREM V8 CatalogPage](#)
- [Catalog Page - PREM S15 CatalogPage](#)
- [Catalog Page - BRY R-14 Catalog Page](#)
- [Catalogs - Bryant Full Line Catalog](#)
- [Catalogs - Premise Wiring Catalog](#)



A Hubbell brand