




# Plates, 1-Gang, With Jack, 6-Position 6-Conductor, Screw Terminal, White

By Bryant  
Catalog # [NS732W](#)

Plates, 1-Gang, With Jack, 6-Position 6-Conductor, Screw Terminal, White

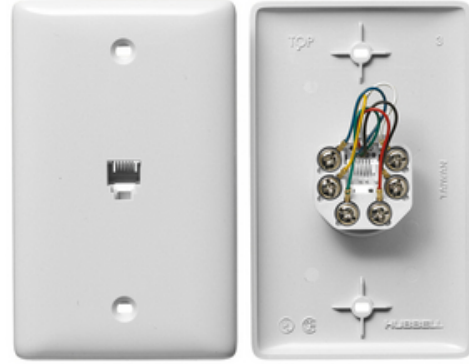

## Features

- Meets FCC part 68
- Convenient screw down terminals
- High impact-resistant thermoplastic plate

## Application

Communications

## General

Color	<ul style="list-style-type: none"><li>• White</li><li>• Blanc</li></ul>
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	1) 6-Position 6-Conductor Jack
Material	Nylon
Material - Mounting Hardware	Screw Mounting
Size	Standard
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	Voice
UPC	883778501371

## Dimensions

Display Size Standard Sized Product

## Electrical Ratings

Connectivity	Screw Terminals
Contact Resistance	Per TIA
Insertion Loss	Per TIA

## Certifications and Compliance

Industry Standard(s) UL Listed

## Logistics

Carton Quantity 10

## Product Assets

[Catalog Page - Bryant R-13 Catalog page](#)  
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-NS732W-SPEC-EN | REV 7/2023