




## Plates, 1-Gang, Mid Sized, With Jack, 6-Position 4-Conductor, Screw Terminal, Light Almond

By Bryant  
Catalog # [NS735LA](#)

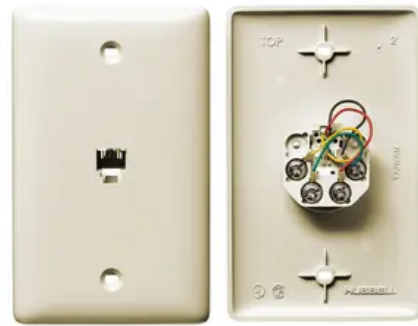

Plates, 1-Gang, Mid Sized, With Jack, 6-Position 4-Conductor, Screw Terminal, Light Almond

### Features

- Meets FCC part 68
- Convenient screw down terminals
- High impact-resistant thermoplastic plate

### Application

Communications

### General

Catalog Number	NS735LA
Color	Light Almond
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	1) 6-Position 4-Conductor Jack
Material	Nylon
Material - Mounting Hardware	Screw Mounting
Size	Midsized
Specifications	<ul style="list-style-type: none"><li>• Device Type - 6-Position, 4-Conductor</li><li>• Style - Mid-Size</li></ul>

Temperature Rating

Max Continuous- 75 Degrees C,  
Minimum- -40 Without Impact

Type  
UPC

Voice  
883778504082

### Dimensions

Display Size

Standard Sized Product

### Electrical Ratings

Connectivity  
Contact Resistance  
Insertion Loss

Screw Terminals  
Per TIA  
Per TIA

### Certifications And Compliance

Industry Standard(s)

UL Listed

### Logistics

Carton Quantity

10

### Product Assets

[Catalog Page - BRY R-13 Catalog Page](#)  
[Catalogs - Bryant Full Line Catalog](#)  
[Specifications - NS735LA](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
BRY-NS735LA-SPEC-EN | REV 10/2024