




# Plates, 1-Gang, With F Connector, Jack, 6-Position 4-Conductor, Screw Terminal, Electric Ivory

By Bryant  
Catalog # [NS7471](#)

Plates, 1-Gang, With F Connector, Jack, 6-Position 4-Conductor, Screw Terminal, Electric Ivory

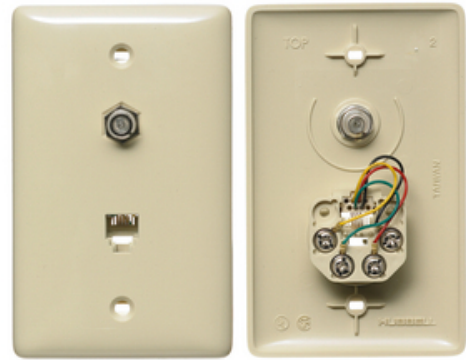

## Features

- Meets FCC part 68
- Convenient screw down terminals
- High impact-resistant thermoplastic plate

## General

Application	Communications
Catalog Number	NS7471
Color	Ivory
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	6-Position 4-Conductor Jack, 1) F-Coax Connector
Material	Nylon
Material - Mounting Hardware	Screw Mounting
Size	Standard
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	Voice & CATV
UPC	883778501616

## Dimensions

Display Size	Standard Sized Product
--------------	------------------------

## Electrical Ratings

Connectivity	Screw Terminals
Contact Resistance	Per TIA
Insertion Loss	Per TIA

## Certifications And Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

## Logistics

Carton Quantity	10
-----------------	----

## Product Assets

- [Catalog Page - PREM S14 CatalogPage](#)
- [Catalog Page - BRY R-13 Catalog Page](#)
- [Catalogs - Bryant Full Line Catalog](#)
- [Catalogs - Premise Wiring Catalog](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
BRY-NS747I-SPEC-EN | REV 6/2024