


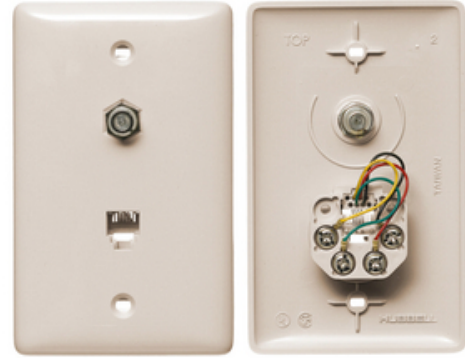

Plates, 1-Gang, With F Connector, Jack, 6-Position 4-Conductor, Screw Terminal, Light Almond

By Bryant
Catalog # [NS747LA](#)

Plates, 1-Gang, With F Connector, Jack, 6-Position 4-Conductor, Screw Terminal, Light Almond



Application

Communications

General

Color	Light Almond/Office White
Construction	Molded
Construction Material - Main	High-Impact Thermoplastic (UL 94V-0)
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	6-Position 4-Conductor Jack, 1) F-Coax Connector
Material	High-Impact Thermoplastic (UL 94V-0)
Material - Mounting Hardware	Screw Mounting
Size	Standard
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	Voice & CATV
UPC	883778503573

Dimensions

Display Size Standard Sized Product

Electrical Ratings

Connectivity	Screw Terminals
Contact Resistance	Per TIA
Insertion Loss	Per TIA

Certifications and Compliance

Industry Standard(s) UL Listed

Logistics

Carton Quantity 10

Product Assets

[Catalog Page - Bryant R-13 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-NS747LA-SPEC-EN | REV 7/2023