




Plates, 1-Gang, With F Connector, Jack, 6-Position 6-Conductor, Screw Terminal, White

By Bryant
Catalog # [NS748W](#)

Plates, 1-Gang, With F Connector, Jack, 6-Position 6-Conductor, Screw Terminal, White

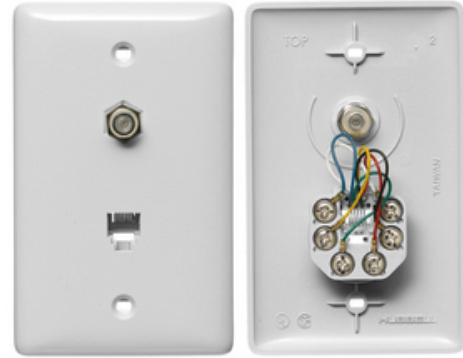

Features

- Meets FCC part 68
- Convenient screw down terminals
- High impact-resistant thermoplastic plate

Application

Communications

General

Color	<ul style="list-style-type: none">• White• Blanc
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	6-Position 6-Conductor Jack, 1) F-Coax Connector
Material	Nylon
Material - Mounting Hardware	Screw Mounting
Size	Standard
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	<ul style="list-style-type: none">• Voice & CATV• Voice & CATV
UPC	883778501647

Dimensions

Display Size Standard Sized Product

Electrical Ratings

Connectivity	Screw Terminals
Contact Resistance	Per TIA
Insertion Loss	Per TIA

Certifications and Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant R-13 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-NS748W-SPEC-EN | REV 7/2023