


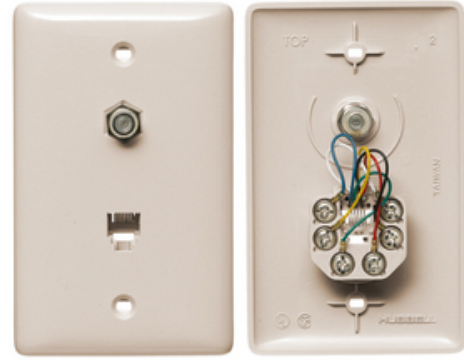

# Plates, 1-Gang, Mid Sized, With F Connector, Jack, 6-Position 6-Conductor, Light Almond

By Bryant  
Catalog # [NS755LA](#)

Plates, 1-Gang, Mid Sized, With F Connector, Jack, 6-Position 6-Conductor, Light Almond



## Features

- Meets FCC part 68
- Convenient screw down terminals
- High impact-resistant thermoplastic plate

## Application

Communications/CATV

## General

Color	Light Almond
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	6-Position 6-Conductor Jack, 1) F-Coax Connector
Material	Nylon
Material - Mounting Hardware	Screw Mounting
Size	Midsized
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	Voice & CATV
UPC	883778504129

## Dimensions

Display Size Standard Sized Product

## Electrical Ratings

Connectivity	Female to Female and 110 IDC
Contact Resistance	Per TIA
Insertion Loss	Per TIA

## Certifications and Compliance

Industry Standard(s) UL Listed

## Logistics

Carton Quantity 10

## Product Assets

[Catalog Page - Bryant R-13 Catalog page](#)  
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-NS755LA-SPEC-EN | REV 7/2023