




Plates, 1-Gang Frame, With Jack, 6-Position 4-Conductor, Screw Terminal, Light Almond

By Bryant
Catalog # NS770LA

Plates, 1-Gang Frame, With Jack, 6- Position 4-Conductor, Screw Terminal, Light Almond

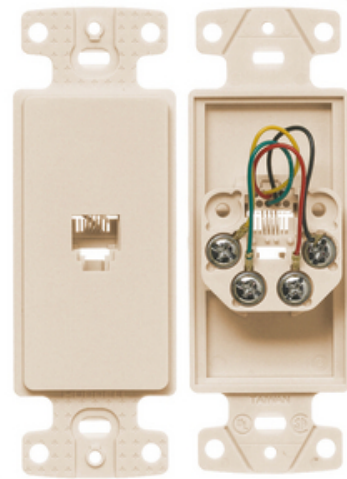

Features

- Meets FCC part 68
- High impact-resistant thermoplastic frame

General

Application	Communications
Catalog Number	NS770LA
Color	Light Almond/Office White
Construction	Molded
Construction Material - Main	High-Impact Thermoplastic (UL 94V-0)
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	1) 6-Position 4-Conductor Jack
Material	High-Impact Thermoplastic (UL 94V-0)
Material - Mounting Hardware	Screw Mounting
Size	Standard
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	Voice and Data
UPC	883778504136

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Connectivity	Screw Terminals
Contact Resistance	Per TIA
Insertion Loss	Per TIA

Certifications And Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog Page - BRY R-12 Catalog Page](#)
- [Catalog Page - PREM S13 CatalogPage](#)
- [Catalogs - Bryant Full Line Catalog](#)
- [Catalogs - Premise Wiring Catalog](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
BRY-NS770LA-SPEC-EN | REV 6/2024