


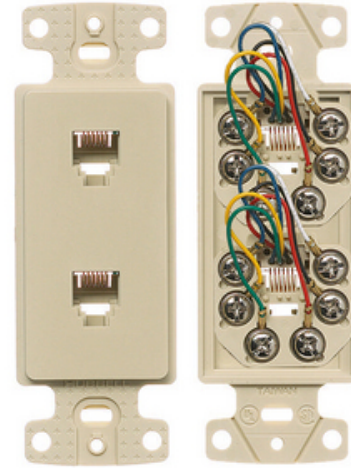

## Plate Frame with 2) Jacks, 6-Position 6-Conductor, Screw Terminal, Electric Ivory

By Bryant  
Catalog # NS772I

Plate Frame with 2) Jacks, 6-Position 6-Conductor, Screw Terminal, Electric Ivory



### Features

- Meets FCC part 68
- High impact-resistant thermoplastic frame

### General

Application	Communications
Catalog Number	NS772I
Color	Ivory
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	2) 6-Position 6-Conductor Jack
Material - Mounting Hardware	Screw Mounting
Size	Standard
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	Voice and Data
UPC	883778501777

### Dimensions

Display Size	Standard Sized Product
--------------	------------------------

### Electrical Ratings

Connectivity	Screw Terminals
Contact Resistance	Per TIA
Insertion Loss	Per TIA

### Certifications And Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

### Logistics

Carton Quantity	10
-----------------	----

### Product Assets

[Catalog Page - BRY R-12 Catalog Page](#)  
[Catalogs - Bryant Full Line Catalog](#)



A Hubbell brand