




Plate Frame with 2) Jacks, 6-Position 6-Conductor, Screw Terminal, Light Almond

By Bryant
Catalog # [NS772LA](#)

Plate Frame with 2) Jacks, 6-Position 6-Conductor, Screw Terminal, Light Almond

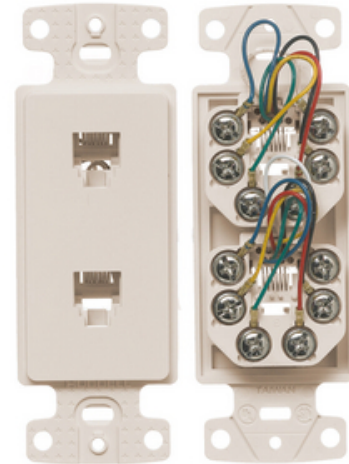

Features

- Meets FCC part 68
- High impact-resistant thermoplastic frame

Application

Communications

General

| | |
|------------------------------|---|
| Catalog Number | NS772LA |
| Color | Light Almond/Office White |
| Construction | Molded |
| Construction Material - Main | High-Impact Thermoplastic (UL 94V-0) |
| Contact | Phosphor Bronze |
| EU RoHS Indicator | Yes |
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means |
| Item Type | 2) 6-Position 6-Conductor Jack |
| Material | High-Impact Thermoplastic (UL 94V-0) |
| Material - Mounting Hardware | Screw Mounting |
| Size | Standard |
| Temperature Rating | Max Continuous- 75 Degrees C, Minimum- -40 Without Impact |
| Type | Voice and Data |
| UPC | 883778503634 |

Dimensions

Display Size Standard Sized Product

Electrical Ratings

| | |
|--------------------|-----------------|
| Connectivity | Screw Terminals |
| Contact Resistance | Per TIA |
| Insertion Loss | Per TIA |

Certifications And Compliance

Industry Standard(s) UL Listed

Logistics

Carton Quantity 10

Product Assets

[Catalog Page - BRY R-12 Catalog Page](#)
[Catalogs - Bryant Full Line Catalog](#)