




Plates, 1-Gang Frame, With Cat5e Jack, 6-Position 4-Conductor, Screw Terminal, Electric Ivory

By Bryant
Catalog # [NS784I](#)

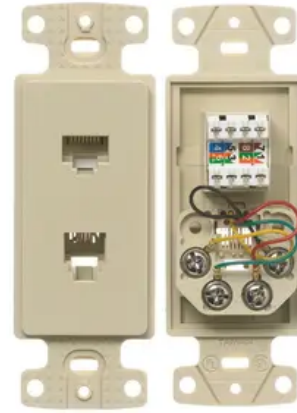

Plates, 1-Gang Frame, With Cat5e Jack, 6-Position 4-Conductor, Screw Terminal, Electric Ivory

Features

- Meets FCC part 68
- High impact-resistant thermoplastic frame

Application

Communications

General

Catalog Number	NS784I
Color	Ivory
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	1) Cat5e, 1) 6-Position 4-Conductor
Material - Mounting Hardware Size	Screw Mounting Standard
Specifications	Device Type - 6-Position, 4-Conductor
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact

Type	Voice and Data
UPC	883778501890

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Connectivity	Screw Terminals
Contact Resistance	Per TIA
Insertion Loss	Per TIA

Certifications And Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog Page - BRY R-12 Catalog Page](#)
- [Catalogs - Bryant Full Line Catalog](#)
- [Specifications - NS784I](#)