




## Net Select, Module, Audio, 8-Port

By Bryant  
Catalog # NSOAM8

Net Select, Module, Audio, 8-Port

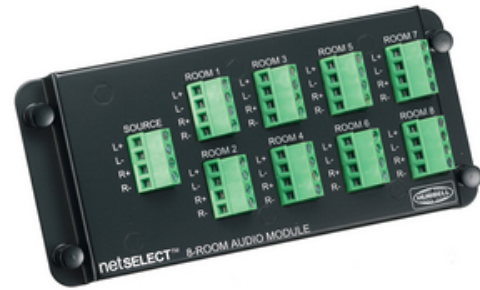

### Application

Analog Audio

### General

Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Enclosure Type	Integral
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	8-Port Audio
Material - Mounting Hardware	Screw Mounting
Style	Audio
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	Audio
UPC	883778500428

### Dimensions

Display Size	Standard Sized Product
--------------	------------------------

### Electrical Ratings

Connectivity	Plug-In
Contact Resistance	Per TIA
Insertion Loss	Per TIA

### Certifications and Compliance

Industry Standard(s)	<ul style="list-style-type: none"><li>RoHS Compliant</li><li>UL and cUL Listed</li></ul>
----------------------	--

### Logistics

Carton Quantity	10
-----------------	----

### Product Assets

[Catalog Page - Bryant R-5 Catalog page](#)  
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-NSOAM8-SPEC-EN | REV 7/2023