




Net Select, Module, Cat6, 8-Port Data

By Bryant
Catalog # [NSODM8C6](#)

Net Select, Module, Cat6, 8-Port Data

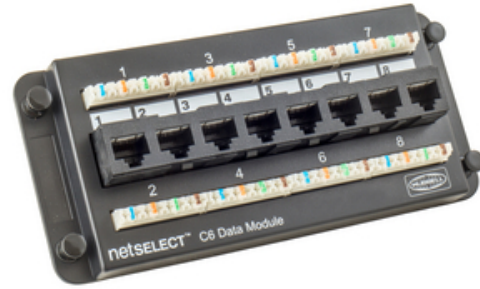

Features

- Meets FCC Part 68 standard
- All data and phone modules 568A wired
- Made of High impact plastic resistant material

Application

Data

General

| | |
|------------------------------|---|
| Contact | Phosphor Bronze |
| EU RoHS Indicator | Yes |
| Enclosure Type | Integral |
| Environmental Conditions | Indoor Dry Unless Protected By Additional Means |
| Item Type | Cat6 8-Port Data |
| Material - Mounting Hardware | Screw Mounting |
| Style | Data |
| Temperature Rating | Max Continuous- 75 Degrees C, Minimum- -40 Without Impact |
| Type | Data |
| UPC | 883778502965 |

Dimensions

Display Size Standard Sized Product

Electrical Ratings

| | |
|--------------------|---------|
| Connectivity | Plug-In |
| Contact Resistance | Per TIA |
| Insertion Loss | Per TIA |

Certifications and Compliance

| | |
|----------------------|---|
| Industry Standard(s) | <ul style="list-style-type: none">• Meets FCC Part 68 Standard• RoHS Compliant• UL and cUL Listed |
|----------------------|---|

Logistics

Carton Quantity 10

Product Assets

[Catalog Page - Bryant R-4 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-NSODM8C6-SPEC-EN | REV 7/2023