




Fiber OSP Breakout Kit, 12 Fiber

By Bryant
Catalog # [OFBOKT12](#)

Tools, OSP Cable Kit, 900 uM, 12-Fiber.

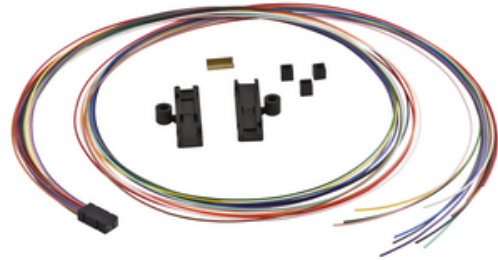

Features

- 36" inch length
- 12 colors EIA/TIA-598
- 12 fiber, 900 micron Furcation Assembly
- 2.4mm Jacket Holding Clip
- 3.0mm Jacket Holding Clip
- Ribbon Jacket Holding Clip
- Brass Jacket Crimp
- Fan-out Housing
- Instruction sheet

Application

OSP Cable Termination

General

EU RoHS Indicator	Yes
Item Type	Tools
Material	PVC (polyvinyl chloride)
Style	OSP Cable Break-Out Kit
Sub Brand	OPTIChannel
Type	<ul style="list-style-type: none">• Tools• Tools
UPC	662620237411

Dimensions

Display Size	900 Micron
--------------	------------

Logistics

Carton Quantity	50
-----------------	----

Product Assets

[Catalog Page - Premise Catalog Page G-18](#)
[Literature - FiberHubb™ Splice-On Connectors](#)
[Literature - PROclick® Fiber Connectors](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-OFBOKT12-SPEC-EN | REV 7/2023