




## Fiber OSP Breakout Kit, 6 Fiber

By Bryant  
Catalog # [OFBOKT6](#)

Tools, OSP Cable Kit, 900 uM, 6-Fiber.

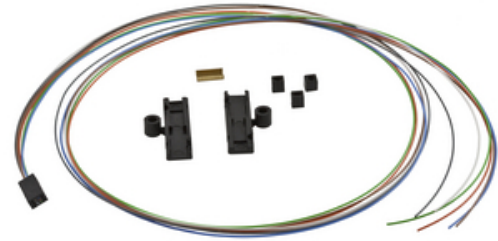

### Features

- 36" inch length
- 6 colors EIA/TIA-598
- 12 fiber, 900 micron Furcation Assembly
- 2.4mm Jacket Holding Clip
- 3.0mm Jacket Holding Clip
- Ribbon Jacket Holding Clip
- Brass Jacket Crimp
- Fan-out Housing
- Instruction sheet

### Application

OSP Cable Termination

### General

EU RoHS Indicator	Yes
Item Type	Tools
Material	PVC (polyvinyl chloride)
Style	OSP Cable Break-Out Kit
Sub Brand	OPTIChannel
Type	<ul style="list-style-type: none"><li>• Tools</li><li>• Tools</li></ul>
UPC	662620237404

### Dimensions

Display Size	900 Micron
--------------	------------

### Logistics

Carton Quantity	50
-----------------	----

### Product Assets

[Catalog Page - Premise Catalog Page G-18](#)  
[Literature - FiberHubb™ Splice-On Connectors](#)  
[Literature - PROclick® Fiber Connectors](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-OFBOKT6-SPEC-EN | REV 7/2023