




# Switches and Lighting Controls, Dimmer for Compact Fluorescent and LED, Single Pole and Three Way, White

By Bryant  
Catalog # RAYCL153PW

Switches and Lighting Controls, Dimmer for Compact Fluorescent and LED, Single Pole and Three Way, White

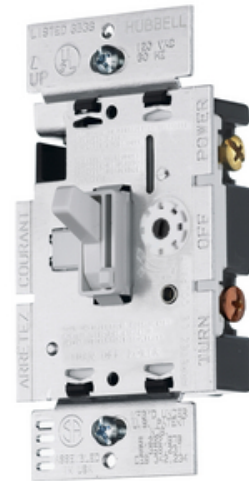

### Features

- Optimum CFL and LED Control
- Low End Adjustment for Fine Tuning
- Decorator and Traditional Toggle Styling Available

### General

Application - For Use On	Only use with Compatible Dimmable Bulbs
Catalog Number	RAYCL153PW
Color	White
Construction	Metal Strap, Polycarbonate Front
EU RoHS Indicator	No
Environmental Conditions	Indoor Use Only
Material - Mounting Hardware	Screws and Wire connectors included
Number Of Poles	Single Pole / 3-Way
Number of Gang(s)	1-Gang
Operating Temperature	32 Deg F to 104 Deg F (0 Deg C to 40 Deg C)
Orientation	Vertical
Style	Toggle Dimmer
Type	LED/CFL
	LED/CFL
UPC	883778304576

### Dimensions

Depth	1.3 in
Height	4.1 in
Width	2.2 in

### Electrical Ratings

Amperage Rating	1.25 A
Voltage Rating	120 VAC
Voltage Rating Description	120V AC
Wattage	150 W

### Certifications And Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

### Logistics

Carton Quantity 6

### Product Assets

[Catalog Page - BRY F-14 Catalog Page](#)  
[Catalogs - Bryant Full Line Catalog](#)



**A Hubbell brand**

©2024 Hubbell Incorporated. All rights reserved  
BRY-RAYCL153PW-SPEC-EN | REV 6/2024