




Switches and Lighting Control, Residential Grade, Motor Speed Control, Toggle Type, Single Pole, 15A 120V AC, White

By Bryant
Catalog # [RAYFSQFW](#)

Switches and Lighting Control, Residential Grade, Motor
Speed Control, Toggle Type, Single Pole, 15A 120V AC, White

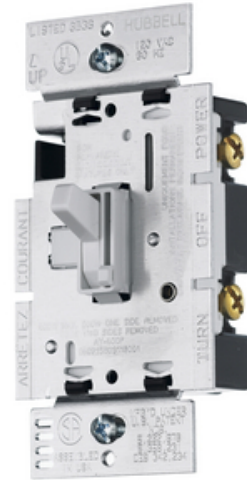

General

Application - For Use On	Only use with Compatible Dimmable Bulbs
Color	<ul style="list-style-type: none">WhiteBlanc
Construction	Metal Strap, Polycarbonate Front
Environmental Conditions	Indoor Use Only
Number Of Poles	Single Pole
Number of Gang(s)	1-Gang
Operating Temperature	32 Deg F to 104 Deg F (0 Deg C to 40 Deg C)
Orientation	Vertical
Style	Toggle Fan Control
Type	Fan Control
UPC	883778116964

Dimensions

Depth	1.3 in
Height	4.1 in
Width	2.2 in

Electrical Ratings

Amperage Rating	1.5 A
Voltage Rating	120 VAC
Voltage Rating Description	120V AC
Wattage	180 W

Certifications and Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

Logistics

Carton Quantity	6
-----------------	---

Product Assets

[Catalog Page - Bryant F-15 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)
[Literature - Residential Catalog](#)

Related Products

[RSFSQFW - TradeSelect, Switches and Lighting Control, Residential Grade, Motor Speed Control, Slider Type, Single Pole, 1.5A 120V AC, White](#)
[RAYFSQFI - Switches and Lighting Control, Residential Grade, Motor Speed Control, Toggle Type, Single Pole, 15A 120V AC, Ivory](#)
[RDVFSQFW - Switches and Lighting Control, Residential Grade, Motor Speed Control, Rocker Type, Single Pole, 1.5A 120V AC, White](#)
[RFSQ2FDK - Switches and Lighting Control, Residential Grade, Motor Speed Control, Pre-Set Rotary Type, Single Pole, 15A 120V AC, Ivory/White](#)
[RAYFSQFLA - Switches and Lighting Control, Residential Grade, Motor Speed Control, Toggle Type, Single Pole, 15A 120V AC, Light Almond](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-RAYFSQFW-SPEC-EN | REV 7/2023