


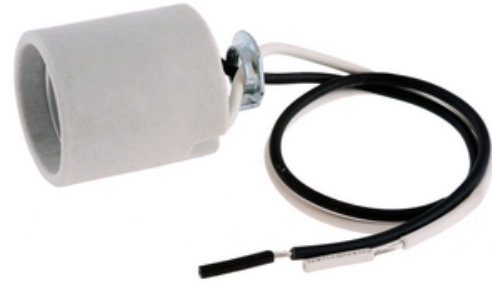

Lampholder, Medium Base, Screw Mount, 12" Leads, White

By Bryant
Catalog # [RL156](#)

Lampholder, Medium Base, Screw Mount, 12" Leads, White



Application

Medium Base, Straight Body Keyless Porcelain

General

Color	<ul style="list-style-type: none">• White• Blanc
Item Type	Replacement Incandescent Lampholders
Lamp Size	Medium Base
Material	Composite
Material - Mounting Hardware	Screw Mounting
Series	Lampholders
Type	Straight Body Keyless Porcelain
UPC	883778304118

Electrical Ratings

Amperage Rating	2.64 A
Connectivity	12" Leads
Current / Amperage Rating	2.64 A
Current Rating	2.64 A
Frequency Rating	60 Hz
Voltage Rating	250V AC kV

Certifications and Compliance

Industry Standard(s) C/US UL Listed

Logistics

Carton Quantity 10

Product Assets

Related Products

[RL159 - Incandescent Lamp Holders, Medium Base, Front Mounted Snap-In, Terminal Screws](#)

[RL160 - Incandescent Lamp Holders, Medium Base, 1/2" Hickey, 12" Wire Leads](#)

[RL158 - Incandescent Lamp Holders, Medium Base, Low Profile, Front Mounted Snap-In, Terminal Screws](#)

[RL162 - Lamp Holders and Sockets, Medium Base, Screw Terminal, Screw Mounted](#)

[RL157 - Incandescent Lamp Holders, Medium Base, 1/2" Hickey, Terminal Screws](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-RL156-SPEC-EN | REV 7/2023