


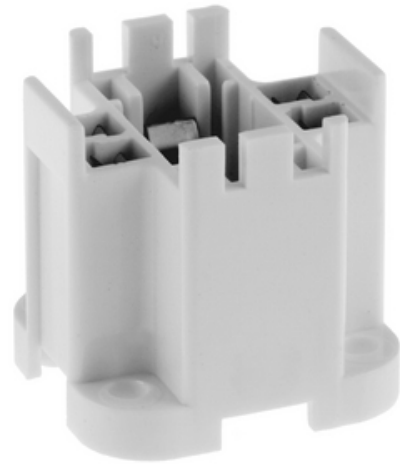

Lampholder, Compact Fluorescent, 26- 32Watt, G24, Horizontal Screw In, White

By Bryant
Catalog # [RL426G24](#)

Lampholder, Compact Fluorescent, 26- 32Watt, G24, Horizontal Screw In, White



Application

Compact Fluorescent

General

Color	<ul style="list-style-type: none">• White• Blanc
Item Type	Fluorescent Lampholders
Lamp Size	G24Q3, GX24-Q4
Material	Composite
Material - Mounting Hardware	Horizontal Screw Down
Performance	<ul style="list-style-type: none">• Electrical - Rating - 26-32W lamp type, 75W, 600V• Mechanical - Terminal Accommodation - Push-in wire terminals for #18 AWG solid or twist and tin stripped 7/16 inch wire
Series	Lampholders
Type	Compact Fluorescent
UPC	883778303944

Electrical Ratings

Connectivity	Screw Terminals
Current Rating	Telephone/CATV
Frequency Rating	60 Hz
Voltage Rating	600V AC kV

Certifications and Compliance

Industry Standard(s)	<ul style="list-style-type: none">• C/US UL Listed• CSA Certified
----------------------	--

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant O-3 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)

Related Products

- [RL413HSI - Fluorescent Lamp Holders, Compact Type, 13 Watt G23X, Horizontal Mount, Snap-In, White](#)
- [RL42G11H9 - Fluorescent Lamp Holders, Compact Type, 18-55 Watt 2G11, 90 Degree Horizontal Mount, Snap-In](#)
- [RL479HSM - Fluorescent Lamp Holders, Compact Type, 9 Watt, Horizontal Screw Mount](#)
- [RL413HSM - Fluorescent Lamp Holders, Compact Type, 13 Watt G23X, Horizontal Mount, Screw Mount, White](#)
- [RL42G11HSM - Fluorescent Lamp Holders, Compact Type, 18-55 Watt 2G11, Horizontal Mount, Snap-In](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-RL426G24-SPEC-EN | REV 7/2023