




TradeSelect, Straight Blade,
Female Connector, Zip Cord,
Polarized, 15A 125V, 2-Pole 2-Wire
Non-Grounding, 1-15R, Black

By Bryant
Catalog # [RP102BK](#)

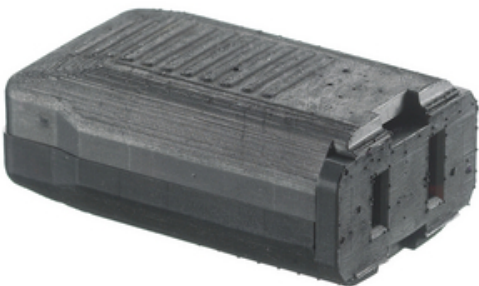

TradeSelect, Straight Blade, Female Connector, Zip Cord,
Polarized, 15A 125V, 2-Pole 2-Wire Non-Grounding, 1-15R, Black

Application

Trade Select Residential Devices

General

Color	<ul style="list-style-type: none">• White• Blanc
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Insulation	Insulated Body
Item Type	Standard
Material	Composite
Material - Mounting Hardware	Cord Mounted
Number Of Poles	2-Pole
Series	Plugs & Connectors
Temperature Rating	Maximum Continuous: 75° C; Minimum Continuous: -40° C w/o impact, -25° with impact.
Type	Connector
UPC	883778112546

Dimensions

Display Size	Standard
--------------	----------

Electrical Ratings

Amperage Rating	15 A
Connectivity	Screw Terminals
Current / Amperage Rating	15 A
Current Rating	15 A
Voltage Rating	125 VAC

Conductor Related

Conductor Range	#16 AWG to #14 AWG
Number Of Conductors	2-Wire Non-Grounding

Certifications and Compliance

Industry Standard(s)	UL Listed
Nema Rating	1-15R

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant A-25 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)

Related Products

- [RP102W - TradeSelect, Straight Blade, Female Connector, Zip Cord, Polarized, 15A 125V, 2-Pole 2-Wire Non-Grounding, 1-15R, White](#)
- [RP101W - TradeSelect, Straight Blade, Male Plug, Light Duty, Polarized, 15A 125V, 2-Pole 2-Wire Non-Grounding, 1-15P, White](#)
- [RP101BK - Straight Blade Devices, Residential Grade, Male Plug, 15A 125V, 2-Pole 2-Wire Non-Grounding, 1-15P, Polarized](#)
- [RT100W - TradeSelect, Cube Tap, 15A 125V AC, 2- Pole 3-Wire Grounding, 5-15R, White](#)
- [RP123PI - Plug, 15A 125V, 2W, POLAR ZIPCORD, Ivory](#)



A proud member of the Hubbell Family.