




TradeSelect, Straight Blade, Female Connector, Zip Cord, Polarized, 15A 125V, 2-Pole 2-Wire Non-Grounding, 1-15R, White

By Bryant
Catalog # [RP102W](#)

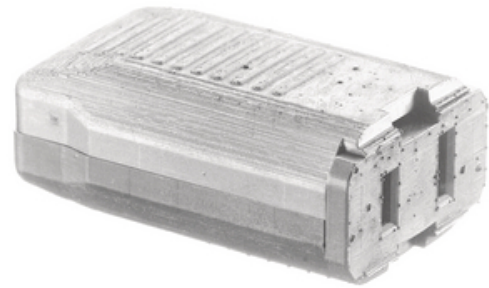

TradeSelect, Straight Blade, Female Connector, Zip Cord, Polarized, 15A 125V, 2-Pole 2-Wire Non-Grounding, 1-15R, White

Application

Trade Select Residential Devices

General

Color	<ul style="list-style-type: none"> • Black • Noir
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Insulation	Insulated Body
Item Type	Standard
Material	Composite
Material - Mounting Hardware	Cord Mounted
Number Of Poles	2-Pole
Series	Plugs & Connectors
Temperature Rating	Maximum Continuous: 75° C; Minimum Continuous: -40° C w/o impact, -25° with impact.
Type	Connector
UPC	883778112539

Dimensions

Display Size	Standard
--------------	----------

Electrical Ratings

Amperage Rating	15 A
Connectivity	Screw Terminals
Current / Amperage Rating	15 A
Current Rating	15 A
Voltage Rating	125 VAC

Conductor Related

Conductor Range	#16 AWG to #14 AWG
Number Of Conductors	2-Wire Non-Grounding

Certifications and Compliance

Industry Standard(s)	UL Listed
Nema Rating	1-15R

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant A-25 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)

Related Products

[RT300I - Adapters, Residential Grade, Single to 3 Outlet, 15A 125V 2-Pole 3-Wire Grounding, Ivory](#)
[9053AB - Locking Devices, Locking Devices, Accessories, Straight Adapter, NEMA 3-Wire Male to 5-15R Female, 2-Pole 3-Wire Grounding, White](#)
[RP123PW - Plug, 15A 125V, 2W, POLAR ZIPCORDER, White](#)
[RP649 - TradeSelect, Straight Blade, Female Connector, 15A 125V, 2-Pole 2-Wire Non-Grounding, 1-15R, .40" Cord Diameter, White](#)
[RP123PI - Plug, 15A 125V, 2W, POLAR ZIPCORDER, Ivory](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-RP102W-SPEC-EN | REV 7/2023