


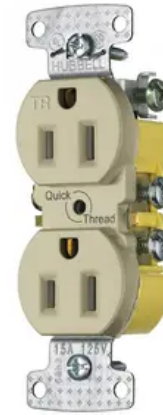

TradeSelect, Straight Blade Receptacles, Residential Grade, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, 8 Hole Push-In Wiring, Light Almond

By Bryant
Catalog # RR15QITR



tradeSELECT® Straight Blade Residential Grade, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, 8 Hole Push-In Wiring

Application

- Residential Receptacles

Performance

- Environmental - Operating temperature - -20°C to 60°C
- Mechanical - Terminal - Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only

General

Catalog Number	RR15QITR
Color	Ivory
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Traditional Duplex
Material	Thermoplastic
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
Specifications	<ul style="list-style-type: none">Base and Cover - Tough thermoplasticProduct Type - ReceptacleReceptacle Type - Duplex Quick ThreadSpring Material - Stainless Steel
UPC	883778301599

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Amperage Rating	15 A
Connectivity	Push and Side Wire
Current / Amperage Rating	15 A
Current Rating	15 A
Phase	Single Phase
Voltage Rating	125 VAC
Voltage Rating Description	125 VAC
Wattage	1875

Conductor Related

Number Of Wires	3-Wire Grounding
Wire Size	#14 AWG to #12 AWG

Certifications And Compliance

Industry Standard(s)	<ul style="list-style-type: none">CSA CertifiedUL Listed E2186
Nema Rating	5-15R
Standards - RoHS Compliance	CM
Status	

Logistics

Carton Quantity	10
Pallet Quantity	9000

Product Assets

- [Catalog Page - WDK Z-16 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Catalogs - Bryant Full Line Catalog](#)
- [Literature - General Literature - Tamper-Resistant and Weather Resistant Receptacles](#)
- [Specifications - RR15QITR](#)