




TradeSelect, Straight Blade Devices, Residential Grade, Receptacles, Weather and Tamper Resistant Duplex, 15A 125V, 5-15R

By Bryant
Catalog # RR15SWRTR

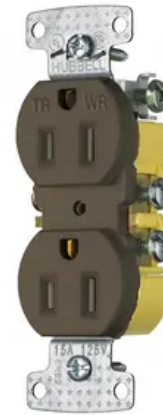

TradeSelect, Straight Blade Devices, Residential Grade, Receptacles, Weather and Tamper Resistant Duplex, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, Self Grounding, Brown

Features

- Smooth indented face appearance
- Multiple-drive Slot/Phillips/Robertson head screws
- Tough thermoplastic ultrasonically welded cover and base

Application

Residential Receptacles

Performance

- Environmental - Operating temperature - -20°C to 60°C
- Mechanical - Terminal - Terminal screws accepts up to #12 AWG, Push wire designed for #14 AWG solid copper wire only

General

Catalog Number	RR15SWRTR
Color	Brown
EU RoHS Indicator	No
Environmental Conditions	Weather Resistant
Item Type	Traditional Duplex
Material	Thermoplastic
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
Specifications	<ul style="list-style-type: none"> • Material - Thermoplastic • Number of Poles - 2 Pole • Product Type - Receptacle • Receptacle Type - Duplex
UPC	883778302992

Dimensions

Display Size

Standard Sized Product

Electrical Ratings

Amperage Rating	15 A
Connectivity	Push and Side Wire
Current / Amperage Rating	15 A
Current Rating	15 A
Phase	Single Phase
Voltage Rating	125 VAC
Voltage Rating Description	125 VAC
Wattage	1875

Conductor Related

Number Of Wires	3-Wire Grounding
Wire Size	#14 AWG to #12 AWG

Certifications And Compliance

Nema Rating	5-15R
-------------	-------

Logistics

Carton Quantity	10
Pallet Quantity	9000

Product Assets

- [Catalog Page - WDK Z-16 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Catalogs - Bryant Full Line Catalog](#)
- [Specifications - RR15SWRTR](#)

