


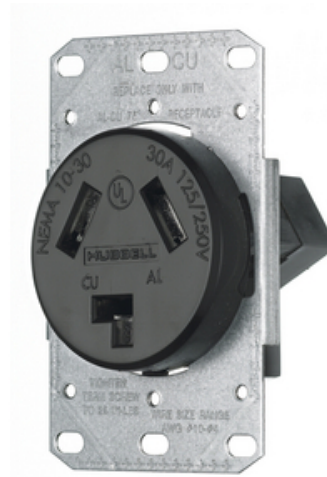

TradeSelect, Straight Blade Devices, Residential Grade, Receptacles, Single, 30A 125/250V, 3-Pole 3-Wire Non- Grounding, 10-30R, Flush Mount, Black

By Bryant
Catalog # [RR330F](#)



tradeSELECT® Straight Blade Residential Grade, Single, 30A 125/250V, 3-Pole 3-Wire Non-Grounding, Flush Mount

Application

Residential Range and Dryer Devices

General

Color	<ul style="list-style-type: none">• Black• Noir
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Material - Mounting Hardware	Screw Mounting
Number Of Poles	3-Pole
Series	Heavy Duty
Style	Smooth Face
Type	Single Receptacle
UPC	883778100796

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Amperage Rating	30 A
Connectivity	Pressure Terminal Screws
Current / Amperage Rating	30 A
Current Rating	30 A
Phase	Single Phase
Voltage Rating	125/250 V
Voltage Rating Description	125/250 V
Wattage	12500

Conductor Related

Number Of Wires	3-Wire
Wire Size	#10 AWG

Certifications and Compliance

Industry Standard(s)	UL Listed
Nema Rating	10-30R

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant A-26 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)

Related Products

[RR335P - TradeSelect, Straight Blade Devices, Residential Grade, Male Plug, 30A 125/250V, 3-Pole 3-Wire Non-Grounding, 10-30P, Polarized](#)
[RR350 - TradeSelect, Straight Blade Devices, Residential Grade, Receptacles, Single, 50A 125/250V, 3-Pole 3-Wire Non-Grounding, 10-50R, Surface Mount, Black](#)
[P703BK - Wallplate, 2-Gang, 2.15" Opening, Black](#)
[RR350F - TradeSelect, Straight Blade Devices, Residential Grade, Receptacles, Single, 50A 125/250V, 3-Pole 3-Wire Non-Grounding, 10-50R, Flush Mount, Black](#)
[RR330 - TradeSelect, Straight Blade Devices, Residential Grade, Receptacles, Single, 30A 125/250V, 3-Pole 3-Wire Non-Grounding, 10-30R, Surface Mount, Black](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-RR330F-SPEC-EN | REV 7/2023