


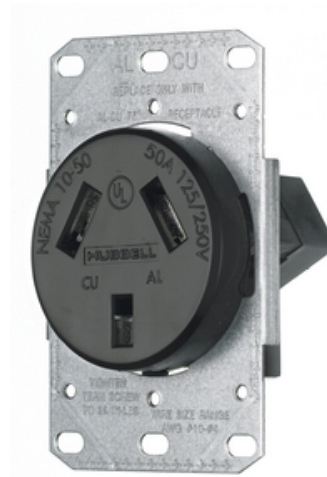

# TradeSelect, Straight Blade Devices, Residential Grade, Receptacles, Single, 50A 125/250V, 3-Pole 3-Wire Non- Grounding, 10-50R, Flush Mount, Black

By Bryant  
Catalog # [RR350F](#)

tradeSELECT® Straight Blade Residential Grade, Single, 50A 125/250V, 3-Pole 3-Wire Non-Grounding, 10-50R, Flush Mount



## Application

Residential Range and Dryer Devices

## General

Color	<ul style="list-style-type: none"><li>• Black</li><li>• Noir</li></ul>
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Material	Thermoplastic
Material - Mounting Hardware	Screw Mounting
Number Of Poles	3-Pole
UPC	883778100802

## Dimensions

Display Size	Standard Sized Product
--------------	------------------------

## Electrical Ratings

Amperage Rating	30 A
Connectivity	Pressure Terminal Screws
Current / Amperage Rating	30 A
Current Rating	30 A
Phase	Single Phase
Voltage Rating	125/250 VAC
Wattage	7500

## Conductor Related

Number Of Wires	3-Wire Non-Grounding
Wire Size	#6 AWG

## Certifications and Compliance

Industry Standard(s)	UL Listed
Nema Rating	10-30R

## Logistics

Carton Quantity	10
-----------------	----

## Product Assets

## Related Products

- [RR335P - TradeSelect, Straight Blade Devices, Residential Grade, Male Plug, 30A 125/250V, 3-Pole 3-Wire Non-Grounding, 10-30P, Polarized](#)
- [P703BK - Wallplate, 2-Gang, 2.15" Opening, Black](#)
- [RR330F - TradeSelect, Straight Blade Devices, Residential Grade, Receptacles, Single, 30A 125/250V, 3-Pole 3-Wire Non-Grounding, 10-30R, Flush Mount, Black](#)
- [P724BK - Wallplate, 1-Gang, 2.15" Opening, Black](#)
- [SS703L - Wallplates and Boxes, Metallic Plates, 2- Gang, 1\) 2.15" Opening, 4 Bolt Mount, 430 Stainless Steel](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-RR350F-SPEC-EN | REV 7/2023