




TradeSelect, Straight Blade, Single Receptacle, Snap-In, 15A 125V, 2-Pole 3-Wire, 5-15, Black

By Bryant
Catalog # RR374

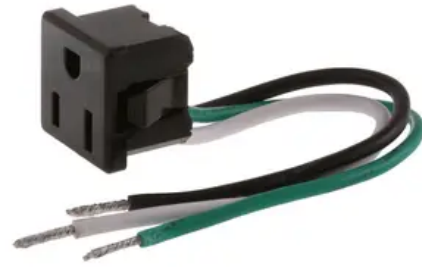

TradeSelect, Straight Blade, Single Receptacle, Snap-In, 15A 125V, 2-Pole 3-Wire, 5-15, Black

Application

- Single Receptacle

Performance

Mechanical - Terminal Accommodation - #14 AWG 6 inch AWM/TEW FT1 105°C 600V on black and white leads, #14 AWG 6 inch AWM/TEW FT1 600V on green lead

General

Catalog Number	RR374
Color	Brown
EU RoHS Indicator	No
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Snap-In Receptacles
Material	Thermoplastic
Material - Mounting Hardware	Snap-In
Number Of Poles	2-Pole
Series	Lampholder Accessories
Type	Snap-In Receptacles
UPC	883778304224

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Amperage Rating	15 A
Connectivity	Wire Leads
Current / Amperage Rating	15 A
Current Rating	15 A
Phase	Single Phase
Voltage Rating	125 VAC
Wattage	1875

Conductor Related

Number Of Wires	3-Wire Grounding
Wire Size	#16 AWG to #14 AWG

Certifications And Compliance

Nema Rating	5-15R
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog Page - WDK BB-9 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Catalogs - Bryant Full Line Catalog](#)
- [Specifications - RR374](#)