




# TradeSelect, Straight Blade, Single Panel Mount Receptacle, 30A 125/250V, 3-Pole 4-Wire Grounding, 14-30R, Black

By Bryant  
Catalog # [RR430PM](#)

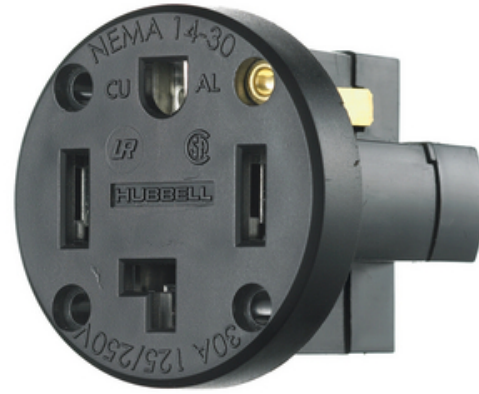

TradeSelect, Straight Blade, Single Panel Mount Receptacle, 30A 125/250V, 3-Pole 4-Wire Grounding, 14-30R, Black

## Application

Residential Range and Dryer Devices

## General

Color	<ul style="list-style-type: none"><li>• Black</li><li>• Noir</li></ul>
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Material - Mounting Hardware	Screw Mounting
Number Of Poles	3-Pole
Series	Heavy Duty
Type	Single Receptacle
UPC	883778100727

## Dimensions

Display Size	Standard Sized Product
--------------	------------------------

## Electrical Ratings

Amperage Rating	30 A
Connectivity	Pressure Terminal Screws
Current / Amperage Rating	30 A
Current Rating	30 A
Phase	Single Phase
Voltage Rating	125/250 V
Voltage Rating Description	125/250 V
Wattage	7500

## Conductor Related

Number Of Wires	4-Wire
Wire Size	#10 AWG

## Certifications and Compliance

Industry Standard(s)	UL Listed
Nema Rating	14-30R

## Logistics

Carton Quantity	50
-----------------	----

## Product Assets

[Catalog Page - Bryant A-26 Catalog page](#)  
[Catalogs - Bryant Full Line Catalog](#)

## Related Products

[RR450 - TradeSelect, Straight Blade Devices, Residential Grade, Receptacles, Single, 50A 125/250V, 3-Pole 4-Wire Grounding, 14-50R, Surface Mount, Black](#)

[RR450PM - TradeSelect, Straight Blade, Single Panel Mount Receptacle, 50A 125/250V, 3-Pole 4-Wire Grounding, 14-50R, Black](#)

[SS703L - Wallplates and Boxes, Metallic Plates, 2- Gang, 1\) 2.15" Opening, 4 Bolt Mount, 430 Stainless Steel](#)

[P724BK - Wallplate, 1-Gang, 2.15" Opening, Black](#)

[RR450WIPCN - TradeSelect, Straight Blade, Single Panel Mount Receptacle, 50A 125/250V, 3-Pole 4-Wire Grounding, 14-50R, Black, With Plate](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-RR430PM-SPEC-EN | REV 7/2023