




# TradeSelect, Straight Blade Devices, Residential Grade, Receptacles, Decorator Duplex, 15A 125V, 2-Pole 3- Wire Grounding, 5-15R, Brown

By Bryant  
Catalog # RRD15

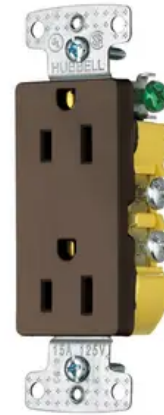

tradeSELECT® Straight Blade Residential Grade, Decorator Duplex, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R

## Features

- Residential Grade
- Receptacles
- Decorator Duplex

## Application

Residential Receptacles

## General

Catalog Number	RRD15
Color	Brown
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Decorator Duplex
Material	Thermoplastic
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
UPC	883778100093

## Dimensions

Display Size	Standard Sized Product
--------------	------------------------

## Electrical Ratings

Amperage Rating	15 A
-----------------	------

Connectivity	Push and Side Wire
Current / Amperage Rating	15 A
Current Rating	15 A
Phase	Single Phase
Voltage Rating	125 VAC
Voltage Rating Description	125 VAC
Wattage	1875

## Conductor Related

Number Of Wires	3-Wire Grounding
Wire Size	#14 AWG to #12 AWG

## Certifications And Compliance

Nema Rating	5-15R
-------------	-------

## Logistics

Carton Quantity	10
Pallet Quantity	10000

## Product Assets

- [Catalog Page - WDK Z-5 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Catalogs - Bryant Full Line Catalog](#)
- [Sales Drawings - WDK\\_RRD15\\_DRAWINGS\\_PDF](#)
- [Specifications - RRD15](#)