




Adapters, Residential Grade, 15A 125V 2- Pole 2-Wire Non-Grounding Male to 15A 125V 2-Pole 3-Wire Grounding Female, Gray

By Bryant
Catalog # [RT200](#)

Adapters, Residential Grade, 15A 125V 2- Pole 2-Wire Non-Grounding Male to 15A 125V 2-Pole 3-Wire Grounding Female, Gray

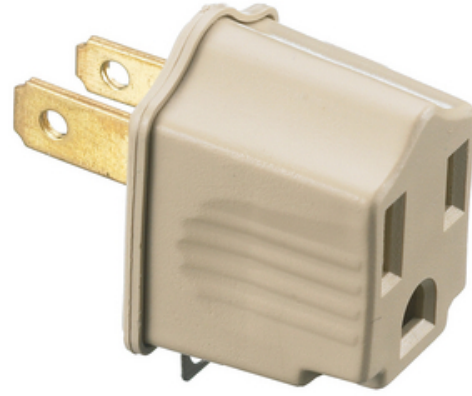

General

Color	Ivory
Insulation	Insulated Body
Item Type	Adapters
Material	Composite
Operating Temperature	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Series	Taps & Adaptors
UPC	883778112454

Electrical Ratings

Amperage Rating	15 A
Current / Amperage Rating	15 A
Current Rating	15 A
Voltage Rating	125 VAC
Wattage	1875

Certifications and Compliance

Industry Standard(s)	C/US UL Listed
----------------------	----------------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant A-25 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)

Related Products

[RT300I - Adapters, Residential Grade, Single to 3 Outlet, 15A 125V 2-Pole 3-Wire Grounding, Ivory](#)
[RT303 - Adapters, Heavy Duty Residential Grade, Single to 3 "X" Outlet, 15A 125V, 2-Pole 3-Wire Grounding, Ivory](#)
[RP646 - TradeSelect, Straight Blade Devices, Residential Grade, Male Plug, 15A 125V, 2-Pole 2-Wire Non-Grounding, 1-15P, Polarized, .40" Cord](#)
[RP649 - TradeSelect, Straight Blade, Female Connector, 15A 125V, 2-Pole 2-Wire Non-Grounding, 1-15R, .40" Cord Diameter, White](#)
[9053AB - Locking Devices, Locking Devices, Accessories, Straight Adapter, NEMA 3-Wire Male to 5-15R Female, 2-Pole 3-Wire Grounding, White](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-RT200-SPEC-EN | REV 7/2023