




Connectors, Speakon Jack, Solder Type, Panel Mount, 10 Pack

By Bryant
Catalog # SC10

Connectors, Speakon Jack, Solder Type, Panel Mount, 10 Pack

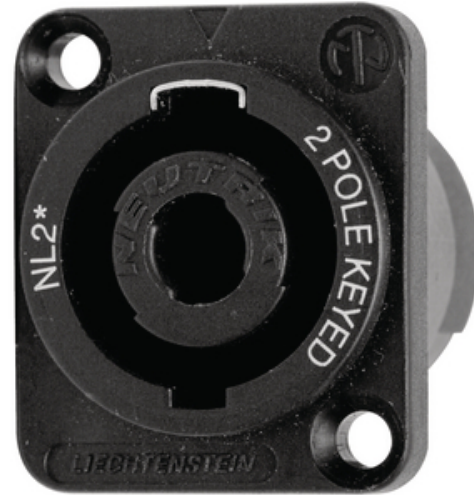

General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION Pro Audio D-Style Connections
Material - Mounting Hardware	Snap-On- Snap-Fit
Temperature Rating	Per TIA
Type	USB
UPC	662620285436

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Connectivity	Solder
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

Logistics

Carton Quantity	5
-----------------	---

Product Assets

[Catalog Page - Bryant R-17 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)

Related Products

[IMAVB15EI - iStation Module, Audio/Video, Unloaded, 1.5-Unit, Electric Ivory, 10 Pack](#)
[IMAVB15GY - iStation Module, Audio/Video, Unloaded, 1.5-Unit, Gray, 10 Pack](#)
[IMAVB15OW - iStation Module, Audio/Video, Unloaded, 1.5-Unit, Office White, 10 Pack](#)
[XLRST10 - XLR Connector, Screw Terminal, Panel Mount, 3-Pin, 10 Pack](#)
[XLR10 - XLR Connector, Solder Type, Panel Mount, 3-Pin, 10 Pack](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-SC10-SPEC-EN | REV 7/2023