




## Snap-Fit, Keystone, USB, A to B, Office White

By Bryant  
Catalog # [SFUSBABOW](#)

Snap-Fit, Keystone, USB, A to B, Office White

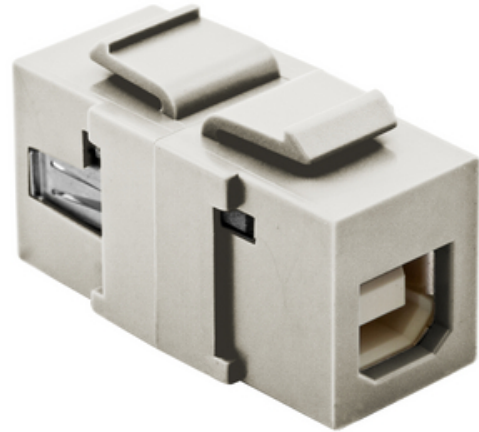

### Application

Snap-Fit USB Jack

### General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION RCA and Data Keystone Connectors
Material - Mounting Hardware	Snap-On- Snap-Fit
Style	USB
Temperature Rating	Per TIA
Type	Data
UPC	662620289168

### Dimensions

Display Size	Standard Sized Product
--------------	------------------------

### Electrical Ratings

Connectivity	Plug-N-Play
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

### Certifications and Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

### Logistics

Carton Quantity	25
-----------------	----

### Product Assets

[Catalog Page - Bryant R-8 Catalog page](#)  
[Catalogs - Bryant Full Line Catalog](#)  
[Literature - Hubbell SystemOne Recessed Fire-Rated Poke-Throughs](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-SFUSBABOW-SPEC-EN | REV 7/2023