




Wallplates and Boxes, Metallic Plates, 2- Gang, 1) Toggle 1) GFCI Opening, Standard Size, Stainless Steel

By Bryant
Catalog # SS126

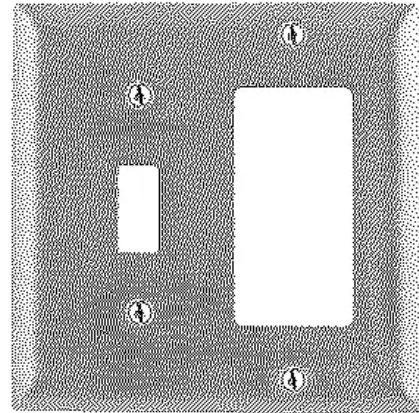

Wallplates and Boxes, Metallic Plates, 2- Gang, 1) Toggle 1) GFCI Opening, Standard Size, Stainless Steel

Application

- Protection against contact of live terminals and wiring. Provides finished look to installation.

General

Catalog Number	SS126
Construction	Stamped
Cutout	1) Toggle, 1) Decorator
EU RoHS Indicator	Yes
Item Type	Screw Mount
Material	Stainless Steel, Type 302/304
Material - Mounting Hardware	Screw Mounting
Number of Gang(s)	2-Gang
Orientation	Vertical Mount
Size	Standard
Specifications	<ul style="list-style-type: none">• Appearance - Horizontal brushed appearance• Material - Stainless steel 302/304• Mounting Screws - 302/304 SS, Slotted head• Plate Openings - Toggle, Decorator• Plate Type - 2-Gang

Style	1-Toggle, 1-Decorator
Type	Combination
UPC	883778200700

Dimensions

Display Size	Standard Sized
Thickness	0.035

Certifications And Compliance

Industry Standard(s)	UL Listed
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	10
Pallet Quantity	8000

Product Assets

- [Catalog Page - WDK AA-45](#)
- [Catalog Page - WDK N-10](#)
- [Catalog Page - WDK Z-13](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Literature - General Literature - Stainless Steel Wallplates Specifications - SS126](#)