




Wallplates and Boxes, Metallic Plates, 2- Gang, 2) Toggle Openings, Standard Size, Stainless Steel

By Bryant
Catalog # SS2

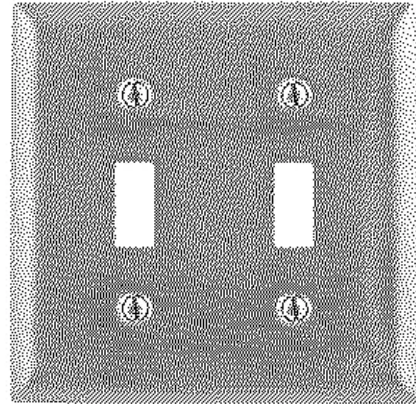

Wallplates and Boxes, Metallic Plates, 2- Gang, 2) Toggle Openings, Standard Size, Stainless Steel

Features

- Ideal for highly corrosive environments
- Non-Magnetic
- Protective plastic film helps to prevent scratches and damage

General

Catalog Number	SS2
Construction	Stamped
Cutout	2) Toggle
EU RoHS Indicator	Yes
Item Type	Toggle Switch Plate
Material	Stainless Steel, Type 302/304
Material - Mounting Hardware	Screw Mounting
Number of Gang(s)	2-Gang
Operating Temperature	-40°C to 85 °C
Orientation	Vertical Mount
Size	Standard
Specifications	<ul style="list-style-type: none">• Appearance - Horizontal brushed finish• Mounting Screws - 302/304 SS, Slotted Head• Plate Material - Stainless steel 302/304• Plate Openings - Toggle switch

Style	• Plate Type - 2-Gang
Type	2-Toggle
UPC	Toggle 883778200809

Dimensions

Display Size	Standard Sized
Thickness	0.035

Certifications And Compliance

Industry Standard(s)	UL Listed
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	10
Pallet Quantity	8000

Product Assets

- [Catalog Page - WDK AA-45](#)
- [Catalog Page - WDK D-19](#)
- [Catalog Page - WDK N-6](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Literature - General Literature - Stainless Steel Wallplates Specifications - SS2](#)