




Wallplates and Boxes, Metallic Plates, 1- Gang, 1) GFCI Opening, Standard Size, Stainless Steel

By Bryant
Catalog # SS26

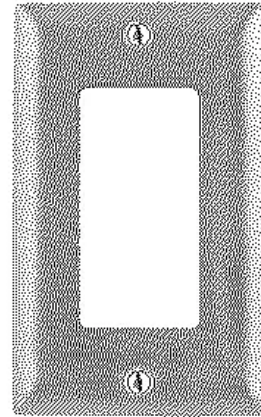

Wallplates and Boxes, Metallic Plates, 1- Gang, 1) GFCI Opening, Standard Size, Stainless Steel.

General

Catalog Number	SS26
Construction	Stamped
Cutout	1) Decorator
EU RoHS Indicator	Yes
Item Type	Screw Mount
Material	Stainless Steel
Material - Mounting Hardware	Screw Mounting
Number of Gang(s)	1-Gang
Operating Temperature	-40°C to 85 °C
Orientation	Vertical Mount
Size	1-Gang
Specifications	<ul style="list-style-type: none"> • Appearance - Horizontal brushed appearance • Material - Stainless steel 302/304 • Mounting Screws - 302/304 SS, Slotted head • Plate Openings - Decorator • Plate Type - 1-Gang
Style	Horizontal Brushed Finish
Type	Plates
UPC	883778200908

Dimensions

Display Size	Standard Sized
Thickness	0.04
Weight	0.05 lb

Certifications And Compliance

Industry Standard(s)	UL Listed
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	10
Pallet Quantity	13200

Product Assets

- [Catalog Page - WDK N-5 Catalog Page](#)
- [Catalog Page - WDK AA-45 Catalog Page](#)
- [Catalog Page - WDK M-13 Catalog Page](#)
- [Catalog Page - WDK A-52 Catalog Page](#)
- [Catalog Page - WDK D-19 Catalog Page](#)
- [Catalog Page - WDK O-39 Catalog Page](#)
- [Catalog Page - WDK Z-12 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Literature - General Literature - Stainless Steel Wallplates Specifications - SS26](#)