




## Wallplates and Boxes, Metallic Plates, 3- Gang, 3) GFCI Openings, Standard Size, Stainless Steel

By Bryant  
Catalog # [SS263](#)

Wallplates and Boxes, Metallic Plates, 3- Gang, 3) GFCI Openings, Standard Size, Stainless Steel

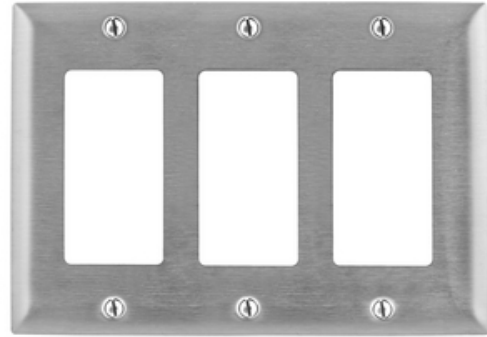

### Features

- Ideal for highly corrosive environments
- Non-magnetic
- Protective plastic film helps to prevent scratches and damage

### Application

Protection against contact of live terminals and wiring.  
Provides finished look to installation.

### General

Color	<ul style="list-style-type: none"><li>• Almond</li><li>• Amande</li></ul>
Construction	Stamped
Cutout	3) Decorator
EU RoHS Indicator	Yes
Item Type	Decorator Wallplates
Material	Stainless Steel, Type 302/304
Material - Mounting Hardware	Screw Mounting
Number of Gang(s)	3-Gang
Operating Temperature	-40°C to 85 °C
Orientation	Vertical Mount
Size	Standard
Style	3-Decorator
Type	<ul style="list-style-type: none"><li>• Decorator</li><li>• Decorator</li></ul>
UPC	883778201684

### Dimensions

Display Size	Standard Sized
Thickness	0.04
Weight	0.2 lb

### Certifications and Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

### Logistics

Carton Quantity	10
-----------------	----

### Product Assets

[Catalog Page - Wiring AA-12 Catalog Page](#)  
[Catalog Page - Bryant Q-5 Catalog page](#)  
[Catalogs - Bryant Full Line Catalog](#)  
[Literature - General Literature - Stainless Steel Wallplates](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
BRY-SS263-SPEC-EN | REV 7/2023