




# Wallplates and Boxes, Metallic Plates, 1- Gang, 1) GFCI Opening, 430 Stainless Steel

By Bryant  
Catalog # SS26L

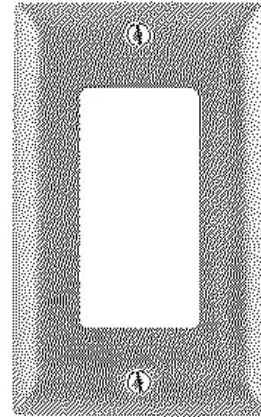

Wallplates and Boxes, Metallic Plates, 1- Gang, 1) GFCI Opening, 430 Stainless Steel

### General

Catalog Number	SS26L
Construction	Stamped
Cutout	1) Decorator
EU RoHS Indicator	No
Item Type	Decorator Wallplates
Material	Stainless Steel, Type 430
Material - Mounting Hardware	Screw Mounting
Number of Gang(s)	1-Gang
Operating Temperature	-40°C to 85 °C
Orientation	Vertical Mount
Size	Standard
Specifications	<ul style="list-style-type: none"> <li>• Appearance - Horizontal brushed appearance</li> <li>• Material - Stainless steel 430</li> <li>• Mounting Screws - 302/304 SS, Slotted head</li> <li>• Plate Openings - Decorator</li> <li>• Plate Type - 1-Gang</li> </ul>
Style	1-Decorator
Type	Decorator

UPC 883778095092

### Dimensions

Display Size Standard Sized  
Thickness 0.035

### Certifications And Compliance

Industry Standard(s) UL Listed

### Logistics

Carton Quantity 10

### Product Assets

- [Catalog Page - WDK N-5 Catalog Page](#)
- [Catalog Page - WDK D-19 Catalog Page](#)
- [Catalog Page - WDK Z-12 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Literature - General Literature - Stainless Steel Wallplates](#)
- [Specifications - SS26L](#)