




Wallplates and Boxes, Metallic Plates, 4- Gang, 3) Toggle 1) GFCI Openings, Standard Size, Stainless Steel

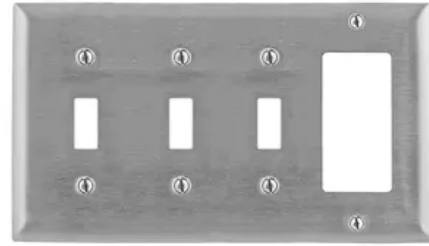

By Bryant
Catalog # SS326

Wallplates and Boxes, Metallic Plates, 4- Gang, 3) Toggle 1) GFCI Openings, Standard Size, Stainless Steel

Features

- Ideal for highly corrosive environments
- Non-magnetic
- Protective plastic film helps to prevent scratches and damage

Application

Protection against contact of live terminals and wiring. Provides finished look to installation.

General

Catalog Number	SS326
Construction	Stamped
Cutout	3) Toggle, 1) Decorator
EU RoHS Indicator	Yes
Item Type	Screw Mount
Material	Stainless Steel, Type 302/304
Material - Mounting Hardware	Screw Mounting
Number of Gang(s)	4-Gang
Orientation	Vertical Mount
Size	Standard
Specifications	<ul style="list-style-type: none"> • Appearance - Horizontal brushed appearance • Material - Stainless steel 302/304

- Mounting Screws - 302/304 SS, Slotted head
 - Plate Openings - Toggle, Decorator
 - Plate Type - 4-Gang 3-Toggle, 1-Decorator Combination
- UPC 883778200953

Style
Type
UPC

Dimensions

Display Size	Standard Sized
Thickness	0.035

Certifications And Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalog Page - WDK N-12 Catalog Page](#)
- [Catalog Page - WDK Z-13 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Specifications - SS326](#)