




Wallplates and Boxes, Metallic Plates, 3- Gang, 3) Toggle Openings, 430 Stainless Steel

By Bryant
Catalog # SS3L

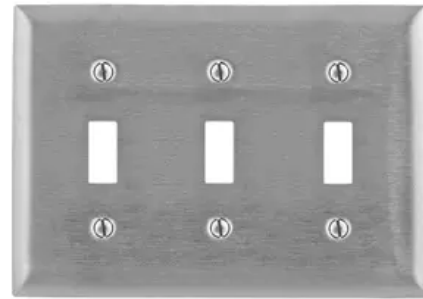

Wallplates and Boxes, Metallic Plates, 3- Gang, 3) Toggle Openings, 430 Stainless Steel

General

Catalog Number	SS3L
Construction	Stamped
Cutout	3) Toggle
EU RoHS Indicator	No
Item Type	Toggle Switch Plate
Material	Stainless Steel, Type 430
Material - Mounting Hardware	Screw Mounting
Number of Gang(s)	3-Gang
Operating Temperature	-40°C to 85 °C
Orientation	Vertical Mount
Size	Standard
Specifications	<ul style="list-style-type: none">• Appearance - Horizontal brushed finish• Mounting Screws - 302/304 SS, Slotted Head• Plate Material - Stainless steel 430• Plate Openings - Toggle switch• Plate Type - 3-Gang

Style	3-Toggle
Type	Toggle
UPC	883778095115

Dimensions

Display Size	Standard Sized
Thickness	0.035

Certifications And Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - WDK D-19 Catalog Page](#)
[Catalog Page - WDK N-6 Catalog Page](#)
[Catalogs - WDK Catalog Full 2024](#)
[Literature - General Literature - Stainless Steel Wallplates Specifications - SS3L](#)