


Wallplates and Boxes, Metallic Plates, 4- Gang, 4) Toggle Openings, Standard Size, Stainless Steel

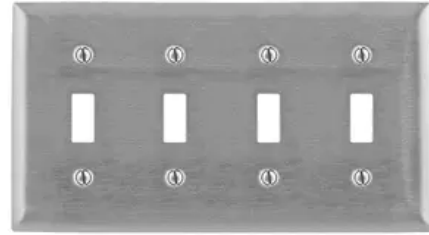

By Bryant
Catalog # SS4

Wallplates and Boxes, Metallic Plates, 4- Gang, 4) Toggle Openings, Standard Size, Stainless Steel

Features

- Ideal for highly corrosive environments
- Non-Magnetic
- Protective plastic film helps to prevent scratches and damage

Application

Protection against contact of live terminals and wiring. Provides finished look to installation.

General

Catalog Number	SS4
Construction	Stamped
Cutout	4) Toggle
EU RoHS Indicator	Yes
Item Type	Screw Mount
Material	Stainless Steel, Type 302/304
Material - Mounting Hardware	Screw Mounting
Number of Gang(s)	4-Gang
Orientation	Vertical Mount
Size	Standard
Specifications	<ul style="list-style-type: none">• Appearance - Horizontal brushed finish• Mounting Screws - 302/304 SS, Slotted Head• Plate Material - Stainless steel 302/304

Style	• Plate Openings - Toggle switch
Type	• Plate Type - 4-Gang 4-Toggle
UPC	Toggle 883778201011

Dimensions

Display Size	Standard Sized
Thickness	0.035

Certifications And Compliance

Industry Standard(s)	UL Listed
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	10
Pallet Quantity	3000

Product Assets

- [BIM - SS4-2](#)
- [BIM - SS4-1](#)
- [Catalog Page - WDK N-6 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Literature - General Literature - Stainless Steel Wallplates Specifications - SS4](#)