


# Wallplates and Boxes, Metallic Plates, 4- Gang, 4) Toggle Openings, Standard Size, Stainless Steel

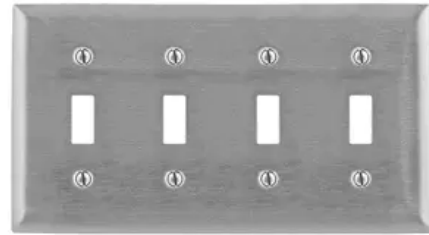

By Bryant  
Catalog # SS4

Wallplates and Boxes, Metallic Plates, 4- Gang, 4) Toggle Openings, Standard Size, Stainless Steel

### Features

- Ideal for highly corrosive environments
- Non-Magnetic
- Protective plastic film helps to prevent scratches and damage

### Application

Protection against contact of live terminals and wiring. Provides finished look to installation.

### General

Catalog Number	SS4
Construction	Stamped
Cutout	4) Toggle
EU RoHS Indicator	Yes
Item Type	Screw Mount
Material	Stainless Steel, Type 302/304
Material - Mounting Hardware	Screw Mounting
Number of Gang(s)	4-Gang
Orientation	Vertical Mount
Size	Standard
Specifications	<ul style="list-style-type: none"> <li>• Appearance - Horizontal brushed finish</li> <li>• Mounting Screws - 302/304 SS, Slotted Head</li> <li>• Plate Material - Stainless steel 302/304</li> <li>• Plate Openings - Toggle switch</li> </ul>

Style	• Plate Type - 4-Gang
Type	4-Toggle
UPC	Toggle 883778201011

### Dimensions

Display Size	Standard Sized
Thickness	0.035

### Certifications And Compliance

Buy America(n) Qualified	TAA Compliant (All status valid till December 2024)
Industry Standard(s)	UL Listed
Standards - RoHS Compliance Status	CM

### Logistics

Carton Quantity	10
Pallet Quantity	3000

### Product Assets

- [BIM - SS4-2](#)
- [BIM - SS4-1](#)
- [Catalog Page - WDK N-6 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Literature - General Literature - Stainless Steel Wallplates Specifications - SS4](#)