


## Wallplates and Boxes, Metallic Plates, 4- Gang, 4) Toggle Openings, 430 Stainless Steel

By Bryant  
Catalog # SS4L

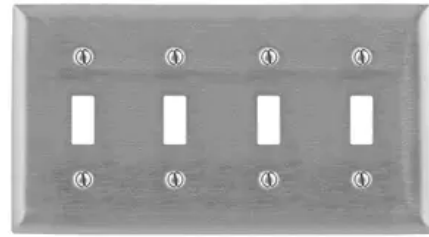

Wallplates and Boxes, Metallic Plates, 4- Gang, 4) Toggle Openings, 430 Stainless Steel

### Application

- Protection against contact of live terminals and wiring. Provides finished look to installation.

### General

Catalog Number	SS4L
Construction	Stamped
Cutout	4) Toggle
EU RoHS Indicator	No
Item Type	Screw Mount
Material	Stainless Steel, Type 430
Material - Mounting Hardware	Screw Mounting
Number of Gang(s)	4-Gang
Orientation	Vertical Mount
Size	Standard
Specifications	<ul style="list-style-type: none"><li>• Appearance - Horizontal brushed finish</li><li>• Mounting Screws - 302/304 SS, Slotted Head</li><li>• Plate Material - Stainless steel 430</li></ul>

Style  
Type  
UPC

- Plate Openings - Toggle switch
  - Plate Type - 4-Gang 4-Toggle Toggle
- 883778095122

### Dimensions

Display Size Standard Sized  
Thickness 0.035

### Certifications And Compliance

Industry Standard(s) UL Listed

### Logistics

Carton Quantity 10

### Product Assets

[Literature - General Literature - Stainless Steel Wallplates Specifications - SS4L](#)