




Wallplates and Boxes, Metallic Plates, 2- Gang, 2) Toggle Openings, Jumbo, Stainless Steel

By Bryant
Catalog # [SSJ2](#)

Wallplates and Boxes, Metallic Plates, 2- Gang, 2) Toggle Openings, Jumbo, Stainless Steel

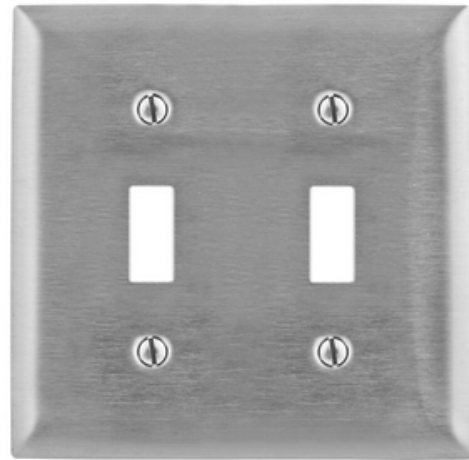

Features

- Environments subjected to heavy abuse
- Non-magnetic: 18.0% Chromium, 8.0% Nickel
- Protective plastic film helps to prevent scratches and damage

Application

Protection against contact of live terminals and wiring.
Provides finished look to installation.

General

Construction	Stamped
Cutout	2) Toggle
EU RoHS Indicator	Yes
Item Type	Screw Mount
Material	Stainless Steel, Type 302/304
Material - Mounting Hardware	Screw Mounting
Number of Gang(s)	2-Gang
Orientation	Vertical Mount
Size	Jumbo
Style	2-Toggle
Type	<ul style="list-style-type: none">• Toggle• Toggle
UPC	883778201486

Dimensions

Display Size	Mid-Sized
Thickness	0.035

Certifications and Compliance

Industry Standard(s)	UL Listed
----------------------	-----------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

[Catalog Page - Bryant Q-14 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)

Related Products

- [SSJ126 - Wallplates and Boxes, Metallic Plates, 2- Gang, 1\) Toggle 1\) GFCI Opening, Jumbo, Stainless Steel](#)
- [SSJ13 - Wallplates and Boxes, Metallic Plates, 1- Gang, Blank, Jumbo, Stainless Steel](#)
- [SSJ18 - Wallplates and Boxes, Metallic Plates, 2- Gang, 1\) Toggle, 1\) Duplex, Jumbo, Stainless Steel](#)
- [SSJ23 - Wallplates and Boxes, Metallic Plates, 2- Gang, Blank, Jumbo, Stainless Steel](#)
- [SSJ82 - Wallplates and Boxes, Metallic Plates, 2- Gang, 2\) Duplex Openings, Jumbo, Stainless Steel, 430 Grade](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-SSJ2-SPEC-EN | REV 7/2023