




Connectors, USB Feed Thru, Panel Mount, 10 Pack

By Bryant
Catalog # [USB10](#)

Connectors, USB Feed Thru, Panel Mount, 10 Pack

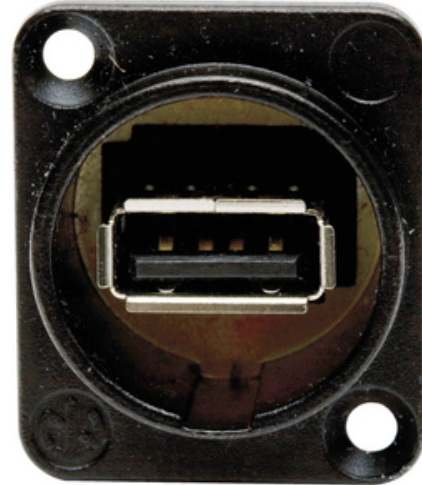

General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION Pro Audio D-Style Connections
Material - Mounting Hardware	Snap-On- Snap-Fit
Temperature Rating	Per TIA
Type	1/4" Locking
UPC	662620285450

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Connectivity	Plug-N-Play
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

Logistics

Carton Quantity	5
-----------------	---

Product Assets

[Catalog Page - Bryant R-17 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)

Related Products

[SC10 - Connectors, Speakon Jack, Solder Type, Panel Mount, 10 Pack](#)
[IMAVB15W - iStation Module, Audio/Video, Unloaded, 1.5-Unit, White, 10 Pack](#)
[IMAVB15GY - iStation Module, Audio/Video, Unloaded, 1.5-Unit, Gray, 10 Pack](#)
[IMAVB15OW - iStation Module, Audio/Video, Unloaded, 1.5-Unit, Office White, 10 Pack](#)
[XLR10 - XLR Connector, Solder Type, Panel Mount, 3-Pin, 10 Pack](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-USB10-SPEC-EN | REV 7/2023