




# USB Charger Duplex Receptacle, 15A 125V, 2-Pole 3-Wire Grounding, 5-15R, 2) 5A USB Ports, Ivory

By Bryant

Catalog # [USBB15A5I](#)

USB Charger Duplex Receptacle, 15A 125V, 2-Pole 3-Wire  
Grounding, 5-15R, 2) 5A USB Ports, Ivory

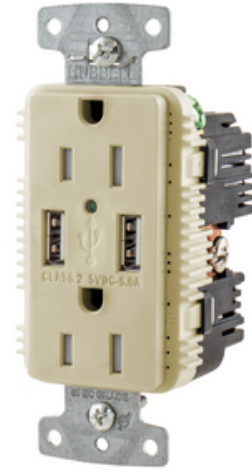

## Features

- High Power 5 Amp, 5 Volt USB Output
- Two Type A USB Ports
- Tamper Resistant Commercial Grade Duplex Compatible
- USB Ports Rated 10,000 Cycles

## General

Color	Ivory
Number Of Poles	2-Pole
Series	Heavy Duty
Style	Style Line Decorator
Type	Two Type A Port
UPC	781786193710

## Electrical Ratings

Current / Amperage Rating	15 A
Voltage Rating	125 V
Voltage Rating Description	125 V

## Conductor Related

Number Of Wires	3-Wire
-----------------	--------

## Certifications And Compliance

Nema Rating	5-15R
-------------	-------

## Logistics

Carton Quantity	10
-----------------	----

## Product Assets

[Catalog Page - BRY A-17 Catalog Page](#)

[Catalogs - Bryant Full Line Catalog](#)



A Hubbell brand