


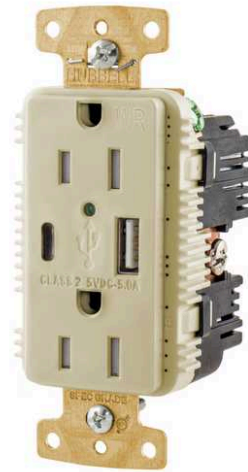

15A/125V Tamper Resistant/Weather Resistant Duplex Receptacle & Type A & C USB Ports, Ivory

By Bryant
Catalog # [USBB15AC5IWR](#)

15A/125V Tamper Resistant/Weather Resistant Duplex Receptacle & Type A & C USB Ports, Ivory



General

UPC 781786917446

Electrical Ratings

Current / Amperage Rating 15 A

Logistics

Carton Quantity 10

Product Assets

[Catalog Page - Bryant A-17 Catalog page](#)
[Catalogs - Bryant Full Line Catalog](#)

Related Products

[USBB15AC5BKWR - 15A/125V Tamper Resistant/Weather Resistant Duplex Receptacle & Type A & C USB Ports, Black P26I - Wallplate, 1-Gang, 1\) Decorator, Ivory](#)
[USBB15AC5GYWR - 15A/125V Tamper Resistant/Weather Resistant Duplex Receptacle & Type A & C USB Ports, Gray](#)
[USBB15AC5WWR - 15A/125V Tamper Resistant/Weather Resistant Duplex Receptacle & Type A & C USB Ports, White](#)
[USBB15AC5LAWR - 15A/125V Tamper Resistant/Weather Resistant Duplex Receptacle & Type A & C USB Ports, Light Almond](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-USBB15AC5IWR-SPEC-EN | REV 7/2023